



SKU  
DS-6-24-170HV-X-QD

Job Name:  
Mark:  
Submitted By:  
Date: 04/25/2025

## Overhead Fan, Product # DS-6-24-170HV-X-QD




Model DS-6 is a six-blade, direct drive HVLS fan designed for commercial or industrial spaces with medium to high ceilings. As the industry's best performing HVLS fan, the DS-6 delivers unrivaled airflow at incredibly quiet sound levels. Along with reduced operating costs, the DS-6 is clearly the best value HVLS product on the market.


- Plug-and-Play
- Safety Retention Cables & Guy Wires
- Impact & Over Speed Detection
- Electrical Safety Systems
- 10-year Warranty

### Certifications

AMCA Circulating Fan Performance  
UL/cUL 507

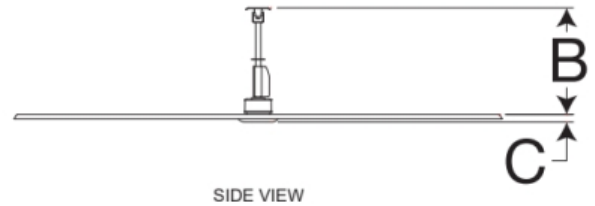

SIDE VIEW

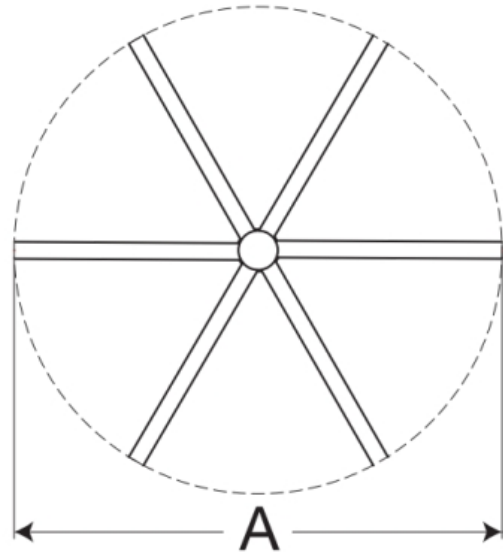

BOTTOM VIEW

A	B	C
288 in	42 in	3 in

### Performance Characteristics

No Fan Curve Available.

### Construction Features

Drive Type	Direct Drive
Impeller Type	Propeller/Axial
Impeller Material	Aluminum
Certifications	AMCA Circulating Fan Performance UL/cUL 507
Speed Controllable	Yes
Blade Color	Mill Finish Aluminum

### Motor Information

Motor Phase	3
Voltage	460
Hertz	60
Motor Enclosure	IP54
RPM	100
Motor Included	Yes